


- **Structural tube**
- Materials: Stainless steel or anodised aluminium
- Square tube 25 x 25mm

Accessories

- Connectors **NCT**
- Caps **BTC**
- Slide profiles **PGT**
- Support profiles **PSP**

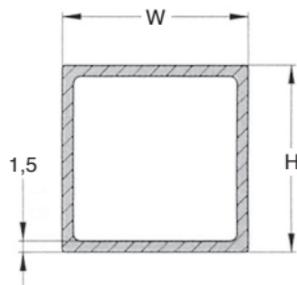

DISCOUNTS

Qty.	1+	10+	21+
Disc.	List -5%	On request	

Part number	Material	H	W	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 9
TUBE25-25/SS	Stainless steel	25	25	3000	3,21	✓	70,08 €
TUBE25-25/AL	Aluminium	25	25	3000	1,09	✓	48,20 €

*Depending on availability - Dimensions in mm

Altri prodotti...



LC

Limitatore di coppia ad attrito, 30 a 240 Nm



PCATherm

Pull handle, Thermoplastic



PCM

Impugnatura cilindrica fissa, Impugnatura non girevole



CFF_SS

Testa a snodo femmina DIN ISO12240-4, Inox / bronzo - Serie



RPCtcss

Ruota girevole a foro centrale, Inox - Poliammide



T2

Cinghia di posizionamento T, T2.5 Poliuretano armatura in acciaio




GBMz

Dado per vite a sfere, Dado cilindrico a circuiti multipli



AC

Piastrina di riscontro, 12,13,18 e 20mm

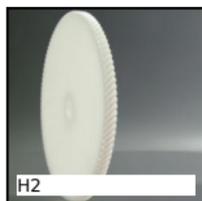

H2

Ingranaggio elicoidale ad assi incrociati a



VBFP

Volantino a 6 lobi - boccola passante,



PRFSRAD

Sistema di chiusura per profili alluminio,



CLAT

Maniglia a ripresa Hygienic Usit®, Inox

Prodotti correlati



BTC

Tappo per tubo quadrato, Standard



NCT_AT

Giunto di collegamento, Ad angolo variabile



NCT

Giunto di collegamento, Ad angolo fisso



NCT

Giunto di collegamento, Ad angolo fisso