


- **Structural tube**
- Materials: Stainless steel or anodised aluminium
- Square tube 25 x 25mm

Accessories

- Connectors **NCT**
- Caps **BTC**
- Slide profiles **PGT**
- Support profiles **PSP**

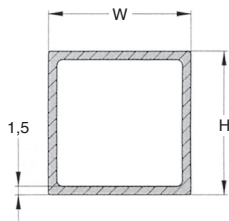


DISCOUNTS

Qty.	1+	10+	21+
Disc.	List -5%	On request	

Part number	Material	H	W	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 9
TUBE25-25/SS	Stainless steel	25	25	3000	3,21	✓	70,08 €
TUBE25-25/AL	Aluminium	25	25	3000	1,09	✓	48,20 €

*Depending on availability - Dimensions in mm

Altri prodotti...

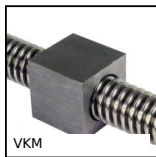

VKM

Dado quadrato in acciaio, Acciaio - 1 filetto



PR820

Ruota di rinvio, Serie 820 e 815



INO

Ingranaggio interno, Acciaio 20NCD2




RHTtcss

Ruota alte temperature con foro centrale, fino a 200kg



BPH

Sfera portante a incastro cilindrico, Forte

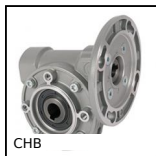

CHB

Riduttore a ruota e vite senza fine, fino a 41 Nm



ACLBTS

Sistema di chiusura, Blocca porta a sfera



DCG

Ventosa, silicone



BABFCFO

Perno autobloccante, Boccole di fissaggio



PV1R

Braccio portaventosa orientabile, Serraggio



CHA60

Cerniera, Rettangolare forata o



SCA_SS

Serracavo, Inox

Prodotti correlati



BTC

Tappo per tubo quadrato, Standard



NCT_AT

Giunto di collegamento, Ad angolo variabile



NCT

Giunto di collegamento, Ad angolo fisso



NCT

Giunto di collegamento, Ad angolo fisso