


- **Operating element**
- **Materials:**
Black phenolic Duraplast
Insert; brass or stainless steel

Advantages


- Easy grip
- Temperature resistant
- Good chemical resistance
- Easier to clean than technopolymer
- In machining applications, less likely to retain swarf

**Good
resistance**

**brass or
stainless steel
insert**

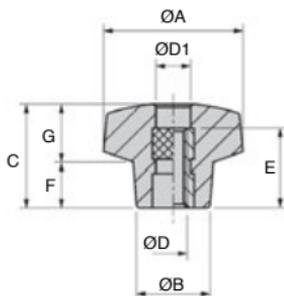

VBFP20-VBFP30-VBFP/SS

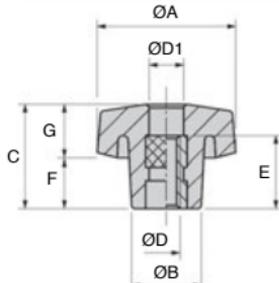

VBFP40 to VBFP70


DISCOUNTS

| Qty | 1+ | 10+ | 20+ | 50+ | 100+ | 200+ |
|-------|------|-----|------|------|------|------------|
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØA | ØB | C | ØD | E | F | G | ØD1 | Weight Price each | |
|-------------------------------|----|----|----|-----|----|----|------|-----|-------------------|---------|
| | | | | | | | | | (g) | 1 to 9 |
| Brass insert | | | | | | | | | | |
| VBFP20-M4 | 20 | 13 | 15 | M4 | 11 | 7 | 8 | 7,5 | 6 | 4,00 € |
| VBFP20-M5 | 20 | 13 | 15 | M5 | 11 | 7 | 8 | 7,5 | 7 | 4,14 € |
| VBFP20-M6 | 20 | 13 | 15 | M6 | 11 | 7 | 8 | 7,5 | 10 | 4,21 € |
| VBFP30-M6 | 30 | 17 | 24 | M6 | 15 | 11 | 12,5 | 9 | 16 | 4,83 € |
| VBFP30-M8 | 30 | 17 | 24 | M8 | 15 | 11 | 12,5 | 9 | 17 | 5,08 € |
| VBFP40-M8 | 40 | 21 | 28 | M8 | 18 | 13 | 15 | 11 | 29 | 5,87 € |
| VBFP40-M10 | 40 | 21 | 28 | M10 | 18 | 13 | 15 | 11 | 31 | 5,91 € |
| VBFP50-M8 | 50 | 25 | 33 | M8 | 18 | 15 | 18 | 13 | 43 | 7,31 € |
| VBFP50-M10 | 50 | 25 | 33 | M10 | 18 | 15 | 18 | 13 | 45 | 7,39 € |
| VBFP50-M12 | 50 | 25 | 33 | M12 | 18 | 15 | 18 | 13 | 47 | 7,39 € |
| VBFP60-M12 | 60 | 28 | 35 | M12 | 25 | 15 | 20 | 13 | 70 | 9,23 € |
| VBFP70-M12 | 70 | 32 | 42 | M12 | 25 | 21 | 21 | 13 | 96 | 11,21 € |
| VBFP70-M14 | 70 | 32 | 42 | M14 | 25 | 21 | 21 | 15 | 94 | 11,21 € |
| VBFP70-M16 | 70 | 32 | 42 | M16 | 25 | 21 | 21 | 17 | 93 | 12,40 € |
| Stainless steel insert | | | | | | | | | | |
| VBFP20-M6/SS | 20 | 13 | 15 | M6 | 11 | 7 | 8 | 7,5 | 10 | 9,19 € |
| VBFP30-M6/SS | 30 | 17 | 24 | M6 | 15 | 11 | 12,5 | 9 | 16 | 9,81 € |
| VBFP40-M8/SS | 40 | 21 | 28 | M8 | 18 | 13 | 15 | 11 | 34 | 10,99 € |
| VBFP50-M8/SS | 50 | 25 | 33 | M8 | 18 | 15 | 18 | 13 | 49 | 11,90 € |
| VBFP50-M10/SS | 50 | 25 | 33 | M10 | 18 | 15 | 18 | 13 | 52 | 12,50 € |

Dimensions in mm

Altri prodotti...

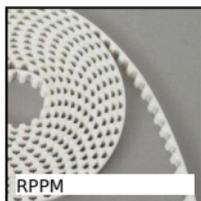

Cinghia aperta al metro tipo RPP, RPP14 Poliuretano armatura in acci...



Pistoncino a molla, Da saldare - Acciaio



Ingranaggio conico - Acciaio C43 - ECO, 1:1




Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



Perno serie corta, Acciaio - serie corta



Perno autobloccante, Inox temprato

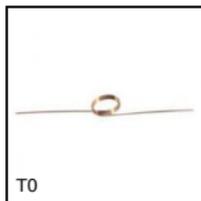

Molla di torsione, Inox



Cerniera (tutto inox), A saldare



Cuscinetto a singola corona di rulli cilindrici, Anello interno con ...



Morsetto di collegamento, Fisso Ø14 a Ø20



Snodo sferico, acciaio/acciaio



Dado cilindrico a passo lungo, Dado cilindrico-fino a 40mm di corsa ...

Prodotti correlati



Volantino a 6 lobi, Duroplast - Acciaio



Piccolo volano a 6 alette, Tecnopolimero - Ottone



Volantino a 3 lobi, Poliammide - Ottone



Volantino a 3 lobi, Poliammide - Ottone