 


- **Dual threaded screw wood/metal**
- Allows a metal object to be fixed to wood
- Materials:
 - Galvanised steel
 - Stainless steel, 304
- Supplied by the pack




Mounting

- Screw should first be inserted into the wood using a suitable spanner
- Compatible with **N, SHN, NINA** and **NIN** nuts



Typical application

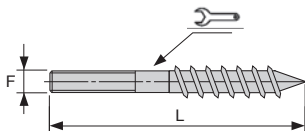

DISCOUNTS Steel

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

DISCOUNTS S/steel

Qty	1+	6+	10+
Disc.	List	-5%	On request

	Part number		ØF	L	Qty per pack		Price each 1 to 5	
	Steel	Stainless steel			Steel	S/steel	Steel	S/steel
VCMB5-40/B		-	M5	40	100	-	5,65 €	-
VCMB5-50/B		-	M5	50	100	-	9,36 €	-
VCMB6-60/B	VCMB6-60/SS/B		M6	60	100	100	11,00 €	36,38 €
VCMB6-80/B	VCMB6-80/SS/B		M6	80	100	100	18,18 €	45,69 €
VCMB6-100/B	VCMB6-100/SS/B		M6	100	100	100	29,76 €	61,45 €
VCMB6-120/B	VCMB6-120/SS/B		M6	120	100	100	30,83 €	69,20 €
VCMB8-50/B	VCMB8-50/SS/B		M8	50	100	100	11,75 €	96,98 €
VCMB8-60/B	VCMB8-60/SS/B		M8	60	100	100	12,67 €	57,14 €
VCMB8-80/B	VCMB8-80/SS/B		M8	80	100	50	16,68 €	38,27 €
VCMB8-100/B	VCMB8-100/SS/B		M8	100	100	50	20,78 €	51,87 €
VCMB8-120/B	VCMB8-120/SS/B		M8	120	100	50	25,32 €	60,40 €
VCMB8-140/B	VCMB8-140/SS/B		M8	140	100	50	32,73 €	70,23 €
VCMB8-160/B	VCMB8-160/SS/B		M8	160	100	50	36,56 €	69,36 €
VCMB10-60/B		-	M10	60	100	-	22,32 €	-
VCMB10-80/B	VCMB10-80/SS/B		M10	80	50	25	15,42 €	46,74 €
VCMB10-100/B	VCMB10-100/SS/B		M10	100	50	25	18,88 €	39,09 €
VCMB10-120/B	VCMB10-120/SS/B		M10	120	50	25	33,04 €	46,29 €
VCMB10-140/B	VCMB10-140/SS/B		M10	140	50	25	42,18 €	50,57 €

Dimensions in mm

Altri prodotti...



SHN
Dado esagonale -
DIN934, Acciaio (Class
6[8])




SH1
Ingranaggio elicoidale
ad assi paralleli,
Plastica lavorata
(delrin)



HG6-ECO
Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45



CHARcav
Cerniera a molla, to
install

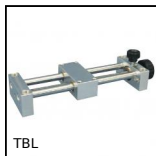

TBL
Mini tavola di
posizionamento a vite
metrica, 1kg



PSG25S
Ingranaggio dritto di
precisione, Inox 316




H3
Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2




BOX-TOR-H
Valigetta di
guarnizioni toriche in
nitrile, 3.00 x 2.00mm
a 45.20 x...



SMS
Ingranaggio conico
spiroidale, 1:1

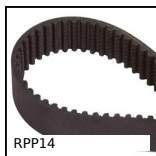

RPP14
Cinghia di
trasmissione RPP,
RPP14

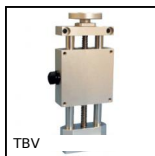

TBV
Tavola di
posizionamento
verticale manuale,



SH4
Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2

Prodotti correlati



VCMB
Vite di giunzione
metallo/legno, Inox



SHN
Dado esagonale -
DIN934, Acciaio (Class
6[8])



NIN
Dado autofrenante ,
Acciaio



SHW
Rondella semplice ,
Acciaio