


- **Dual threaded screw wood/metal**
- Allows a metal object to be fixed to wood
- Materials:
 - Galvanised steel
 - Stainless steel, 304
- Supplied by the pack




Mounting

- Screw should first be inserted into the wood using a suitable spanner
- Compatible with **N, SHN, NINA** and **NIN** nuts

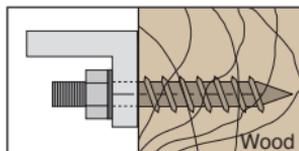

Typical application

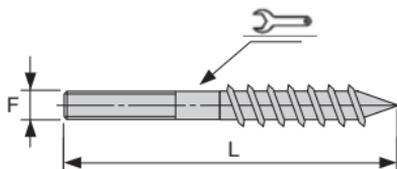

DISCOUNTS Steel

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

DISCOUNTS S/steel

Qty	1+	6+	10+
Disc.	List	-5%	On request

	Part number		ØF	L	Qty per pack		Price each 1 to 5	
	Steel	Stainless steel			Steel	S/steel	Steel	S/steel
VCMB5-40/B		-	M5	40	100	-	5,65 €	-
VCMB5-50/B		-	M5	50	100	-	9,36 €	-
VCMB6-60/B	VCMB6-60/SS/B		M6	60	100	100	11,00 €	36,38 €
VCMB6-80/B	VCMB6-80/SS/B		M6	80	100	100	18,18 €	45,69 €
VCMB6-100/B	VCMB6-100/SS/B		M6	100	100	100	29,76 €	61,45 €
VCMB6-120/B	VCMB6-120/SS/B		M6	120	100	100	30,83 €	69,20 €
VCMB8-50/B	VCMB8-50/SS/B		M8	50	100	100	11,75 €	96,98 €
VCMB8-60/B	VCMB8-60/SS/B		M8	60	100	100	12,67 €	57,14 €
VCMB8-80/B	VCMB8-80/SS/B		M8	80	100	50	16,68 €	38,27 €
VCMB8-100/B	VCMB8-100/SS/B		M8	100	100	50	20,78 €	51,87 €
VCMB8-120/B	VCMB8-120/SS/B		M8	120	100	50	25,32 €	60,40 €
VCMB8-140/B	VCMB8-140/SS/B		M8	140	100	50	32,73 €	70,23 €
VCMB8-160/B	VCMB8-160/SS/B		M8	160	100	50	36,56 €	69,36 €
VCMB10-60/B		-	M10	60	100	-	22,32 €	-
VCMB10-80/B	VCMB10-80/SS/B		M10	80	50	25	15,42 €	46,74 €
VCMB10-100/B	VCMB10-100/SS/B		M10	100	50	25	18,88 €	39,09 €
VCMB10-120/B	VCMB10-120/SS/B		M10	120	50	25	33,04 €	46,29 €
VCMB10-140/B	VCMB10-140/SS/B		M10	140	50	25	42,18 €	50,57 €

Dimensions in mm

Altri prodotti...



DCG

Ventosa, Gomma naturale



Q4

Cuscinetto a doppia corona di sfere, Radiale - Acciaio



EKONSL

Piedino antivibrante conico silicone, Fissaggio femmina



SHN

Dado esagonale - DIN934, Inox A2



M1

Ruota per vite senza fine, Bronzo



CHT

Motore AC asincrono trifase, 0.55 a 1.1kW



GMK17_BROSSE

Spazzola, Per imbottigliamento e imballaggio



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



BLHM40

Rinvio angolare, fino a 10.3 Nm



CM_CO

Attrezzi Hygienic Usit® and Hygienic Design®, Protective



CT

Giunto cardanico telescopico, Sollecitazioni normale



VHTM

Hexagonal headed bolt Hygienic Design®, Inox

Prodotti correlati



VCMB

Vite di giunzione metallo/legno, Acciaio



SHN

Dado esagonale - DIN934, Inox A2



NIN

Dado autofrenante, Inox A2



SHW

Rondella semplice, Inox A2