

Clip-on base for hook-and-loop strip

For electric and pneumatic cables **VELPRF**

- Support clip for Velcro type hook-and-loop strip
- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0






Advantages

- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe

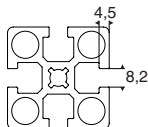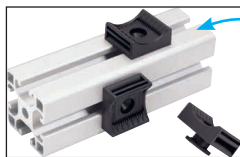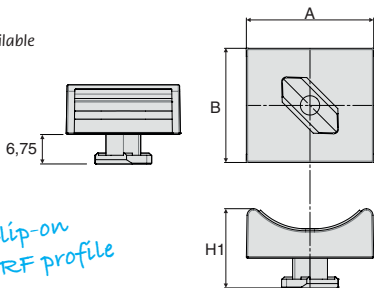

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List		-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each	
						1 to 9	10 to 99
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €	3,85 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €	3,85 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,32 €	4,02 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,47 €	4,17 €

*Depending on availability - Dimensions in mm

Altri prodotti...



STRIP1000

Spazzola strip,
Lunghezza 1m



BPTR

Tappo per tubo tondo,
Standard



PPRss

Piastrina con anello,
Inox



ZG125

Ingranaggio dritto in
plastica, Plastica
lavorata (delrin)




PSG15

Ingranaggio dritto di
precisione, Acciaio
20NCD2 cementato
temprato



BLHB30

Rinvio angolare ad
albero cavo, fino a
4.47 Nm

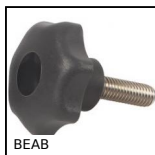

BEAB

Manopola, stella,
antibatterico



RFK58C

Riduttore ipoide inox,
fino a 500 Nm



CFUURSS

Perno folle inox,
Standard - inox



ALIDR30

Alimentazione, 1,5 A
and 2 A



BIM

Pistoncino a molla,
miniatura



RCX-6

Rondella sferica -
DIN6319, convessa

Prodotti correlati



VEL

Rotolo a strappo
fermacavi, cavi
elettrici e pneumatici



VELM4

Supporto avvitabile
per rotolo a strappo
fermacavi,
Poliammide



VELM6

Supporto avvitabile
per rotolo a strappo
fermacavi,
Poliammide