

Clip-on base for hook-and-loop strip

For electric and pneumatic cables **VELPRF**

- Support clip for Velcro type hook-and-loop strip
- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0






Advantages

- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe

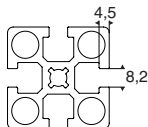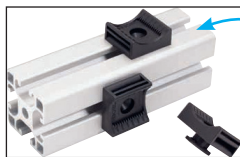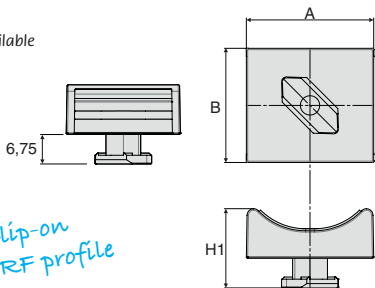

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List		-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each
						1 to 9
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,32 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,47 €

*Depending on availability - Dimensions in mm

Altri prodotti...



RAS

Snodo angolare a 90°
DIN71802, Inox




PR40

Piede fissabile con
snodo - poliammide, Ø
50



EHD16

Riduttore coassiale,
da 210 a 380 Nm

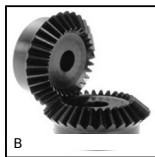

B

Ingranaggio conico -
Acciaio 60C40, 1:1



MDB_MTB

Ingranaggio conico in
plastica stampata ,
2:1



KSTM

Supporto ritto con
cuscinetto Igubal®,
Polimero



CHN_CHNSS

Catena dritta a maglie
lunghe, Acciaio
zincato



E20

Riduttore a rinvio
angolare, da 0.60 a
3.84 Nm



WJUM20

Pattino Drylin® W,
Pattino



RT25

Caletto di
bloccaggio, Coppia
media/elevata



SCH

Attrezzo di
bloccaggio, A tirante
orizzontale - inox



F7-I

Visualizzatore
multifunzione, Con
sensore di posizione
integrato

Prodotti correlati



VEL

Rotolo a strappo
fermacavi, cavi
elettrici e pneumatici



VELM4

Supporto avvitabile
per rotolo a strappo
fermacavi,
Poliammide



VELM6

Supporto avvitabile
per rotolo a strappo
fermacavi,
Poliammide