

Clip-on base for hook-and-loop strip

For electric and pneumatic cables **VELPRF**

- Support clip for Velcro type hook-and-loop strip
- Connecting element for fixing a cable on a **Minitec PRF** aluminum profile
- Anti-return clip (the strips can only pass in one direction) for optimum cable tightening
- Materials:
Glass fiber reinforced polyamide
self-extinguishing according to UL94-V0






Advantages

- Easy mounting by 45° rotation
- Reusable
- Different sizes of hook-and-loop strips available

Accessories

- VEL stripe

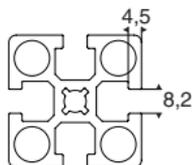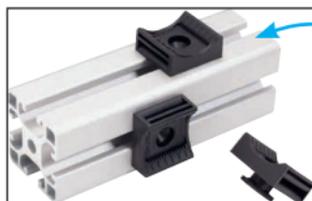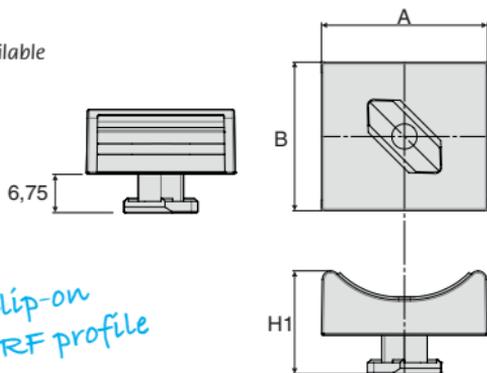

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List		-5%	-10%	On request

Part number	Range of Tightening (mm)	For strip Width (mm)	A	B	H1	Price each	
						1 to 9	10 to 99
VEL7.5-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €	3,90 €
VEL10-PRF-420	4-20	7,5/10	19	15	15,35	4,15 €	3,90 €
VEL20-PRF-835	8-35	20	29	26	18,05	4,32 €	4,05 €
VEL20-PRF-1060	10-60	20	36	26	18,05	4,47 €	4,20 €

*Depending on availability - Dimensions in mm

Altri prodotti...



PRF_BP

Maniglia e battuta per porta, Arresto per porta a battente



PGT

Accessori per pannello, Profilo per pannello scorrevole



BPVMss

Sfera portante avvitabile miniatura, Miniatura ad avvitare



BS3

Panamech, Multi-Beam inox, Inox - con vite a pressione



PPS

Anello di sollevamento, Gancio universale ad avvitare



ZBconique

Ingranaggio conico in plastica, 1:1



SSB

Ingranaggio conico inox, 1:1



TK

Manicotto a sfere autoallineante Topball, Autoallineante,




GCL

Guida lineare a sfere - Sfere inox, Carello - da 516 N a 8396 N



CHV

Motovariatore meccanico, da 0,18 a 1,5kW

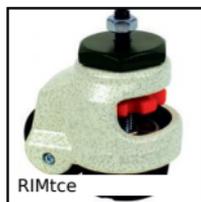

RIMtce

Ruota di livellamento, Con foro centrale



MET

Cuscinetto cilindrico, Self-lubricating sintered bronze

Prodotti correlati



VEL

Rotolo a strappo fermacavi, cavi elettrici e pneumatici



VELM4

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide



VELM6

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide