


Hexagonal headed bolts, **DIN 933**

New**VTH****Zinc plated steel (Class 8.8)**

- Bolt conforming to DIN 933
- Full thread
- Material:
 - Zinc plated steel (Class 8.8)
- Mechanical characteristics conform to ISO 898-1
- Supplied by the packet

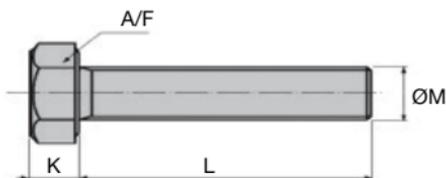

DISCOUNTS

| | | | | |
|-------------|------|-----|------|------------|
| No. packets | 1+ | 6+ | 20+ | 50+ |
| Discounts | List | -5% | -20% | On request |

| Part number | ØM | Pitch | | K | A/F across flats | Qty per packet | Price each |
|-------------|----|-------|----|------|---------------------|-------------------|------------|
| | | P | L | | | | 1 to 5 |
| VTH4-10/B | M4 | 0,70 | 10 | 2,92 | 7,0 | 500 | 11,28 € |
| VTH4-12/B | M4 | 0,70 | 12 | 2,92 | 7,0 | 500 | 12,42 € |
| VTH4-16/B | M4 | 0,70 | 16 | 2,92 | 7,0 | 500 | 14,68 € |
| VTH4-20/B | M4 | 0,70 | 20 | 2,92 | 7,0 | 500 | 16,56 € |
| VTH4-25/B | M4 | 0,70 | 25 | 2,92 | 7,0 | 500 | 19,56 € |
| VTH4-30/B | M4 | 0,70 | 30 | 2,92 | 7,0 | 500 | 22,19 € |
| VTH4-35/B | M4 | 0,70 | 35 | 2,92 | 7,0 | 200 | 13,84 € |
| VTH4-40/B | M4 | 0,70 | 40 | 2,92 | 7,0 | 200 | 15,51 € |
| VTH5-10/B | M5 | 0,80 | 10 | 3,65 | 8,0 | 500 | 11,43 € |
| VTH5-12/B | M5 | 0,80 | 12 | 3,65 | 8,0 | 500 | 12,64 € |
| VTH5-16/B | M5 | 0,80 | 16 | 3,65 | 8,0 | 500 | 14,74 € |
| VTH5-20/B | M5 | 0,80 | 20 | 3,65 | 8,0 | 500 | 16,87 € |
| VTH5-25/B | M5 | 0,80 | 25 | 3,65 | 8,0 | 500 | 19,56 € |
| VTH5-30/B | M5 | 0,80 | 30 | 3,65 | 8,0 | 500 | 22,28 € |
| VTH5-35/B | M5 | 0,80 | 35 | 3,65 | 8,0 | 200 | 10,01 € |
| VTH5-40/B | M5 | 0,80 | 40 | 3,65 | 8,0 | 200 | 11,06 € |
| VTH5-45/B | M5 | 0,80 | 45 | 3,65 | 8,0 | 200 | 15,20 € |
| VTH5-50/B | M5 | 0,80 | 50 | 3,65 | 8,0 | 200 | 16,84 € |

Dimensions in mm

DISCOUNTS

| No. packets | 1+ | 6+ | 20+ | 50+ |
|-------------|------|-----|------|------------|
| Discounts | List | -5% | -20% | On request |

| Part number | ØM | Pitch | | | A/F | Qty | Price each |
|-------------|-----|-------|-----|------|------|-----|------------|
| | | P | L | K | | | |
| VTH6-10/B | M6 | 1,00 | 10 | 4,15 | 10,0 | 500 | 22,19 € |
| VTH6-16/B | M6 | 1,00 | 16 | 4,15 | 10,0 | 500 | 18,69 € |
| VTH6-20/B | M6 | 1,00 | 20 | 4,15 | 10,0 | 500 | 21,07 € |
| VTH6-25/B | M6 | 1,00 | 25 | 4,15 | 10,0 | 500 | 24,23 € |
| VTH6-30/B | M6 | 1,00 | 30 | 4,15 | 10,0 | 500 | 27,38 € |
| VTH6-40/B | M6 | 1,00 | 40 | 4,15 | 10,0 | 200 | 13,50 € |
| VTH6-50/B | M6 | 1,00 | 50 | 4,15 | 10,0 | 200 | 16,04 € |
| VTH6-60/B | M6 | 1,00 | 60 | 4,15 | 10,0 | 200 | 21,20 € |
| VTH8-20/B | M8 | 1,25 | 20 | 5,45 | 13,0 | 200 | 17,09 € |
| VTH8-30/B | M8 | 1,25 | 30 | 5,45 | 13,0 | 200 | 21,51 € |
| VTH8-40/B | M8 | 1,25 | 40 | 5,45 | 13,0 | 100 | 13,01 € |
| VTH8-50/B | M8 | 1,25 | 50 | 5,45 | 13,0 | 100 | 15,11 € |
| VTH8-60/B | M8 | 1,25 | 60 | 5,45 | 13,0 | 100 | 17,40 € |
| VTH8-70/B | M8 | 1,25 | 70 | 5,45 | 13,0 | 100 | 19,59 € |
| VTH8-80/B | M8 | 1,25 | 80 | 5,45 | 13,0 | 100 | 21,82 € |
| VTH10-20/B | M10 | 1,50 | 20 | 6,58 | 17,0 | 200 | 29,51 € |
| VTH10-30/B | M10 | 1,50 | 30 | 6,58 | 17,0 | 200 | 36,46 € |
| VTH10-40/B | M10 | 1,50 | 40 | 6,58 | 17,0 | 100 | 21,66 € |
| VTH10-50/B | M10 | 1,50 | 50 | 6,58 | 17,0 | 100 | 25,12 € |
| VTH10-60/B | M10 | 1,50 | 60 | 6,58 | 17,0 | 50 | 14,37 € |
| VTH10-70/B | M10 | 1,50 | 70 | 6,58 | 17,0 | 50 | 16,10 € |
| VTH10-80/B | M10 | 1,50 | 80 | 6,58 | 17,0 | 50 | 17,83 € |
| VTH10-100/B | M10 | 1,50 | 100 | 6,58 | 17,0 | 50 | 21,29 € |
| VTH12-20/B | M12 | 1,75 | 20 | 7,68 | 19,0 | 100 | 21,54 € |
| VTH12-35/B | M12 | 1,75 | 35 | 7,68 | 19,0 | 100 | 28,71 € |
| VTH12-45/B | M12 | 1,75 | 45 | 7,68 | 19,0 | 100 | 33,71 € |
| VTH12-55/B | M12 | 1,75 | 55 | 7,68 | 19,0 | 50 | 19,31 € |
| VTH12-60/B | M12 | 1,75 | 60 | 7,68 | 19,0 | 50 | 20,24 € |
| VTH12-70/B | M12 | 1,75 | 70 | 7,68 | 19,0 | 50 | 23,08 € |
| VTH12-80/B | M12 | 1,75 | 80 | 7,68 | 19,0 | 50 | 25,59 € |
| VTH12-100/B | M12 | 1,75 | 100 | 7,68 | 19,0 | 50 | 30,59 € |

Dimensions in mm

Altri prodotti...



BAC105

Contenitore a becco,
8mm



HLA19

Rinvio angolare a
dentatura spiroidale,
Fino a 43Nm



GP

Chiusura a leva molla
a trazione
compensata,
Standard



DTR

Pignone tendicateni,
Ruota dentata in
plastica



CHA138

Cerniera ad avvitare,
138 gradi



ZG2

Ingranaggio dritto in
plastica, Plastica
lavorata (delrin)



FDSQ

Flexible drive shaft,
Masterflex® Steel,
with PVC casing



DOMI80

Accessori di
collegamento, Piatto
girevole



MLY

Grillo con chiodo ad
occhiello, Acciaio



PCP

Kit connettori per
portacellule, Pre-
assemblato



SVG

Chiusura a leva
regolabile, Corsa da
174mm a 190mm



EX

Albero per riduttori E,
Albero semplice per
riduttori E

Prodotti correlati



SHN

Dado esagonale -
DIN934, Acciaio (Class
6/8)



BHEx

Tappo di protezione
esagonale,
Tecnopolimero nero



NIN

Dado autofrenante ,
Acciaio



SHW

Rondella semplice ,
Acciaio