


- **Ball head screws**
- Specially designed component for fixing cladding panels, Plexiglass screens etc
- Material:
 - Stainless steel 1.4404 (316L)
 - Polished finish $RA < 0.8$

Advantages

- The oversized flange and the thread undercut ensure a stress-free, uniform force distribution on the supported element.
- Optimised form for use in hygienic environments.
- Dirt and residue from products or cleaners are practically non-adherent, guaranteeing easy cleaning

Accessories

- For tightening and loosening the screws without damaging them, use the **CM flat spanner** with protective cap (**tome 1 p.628**) in combination with the **CM-CF** accessory (**tome 1 p.629**)

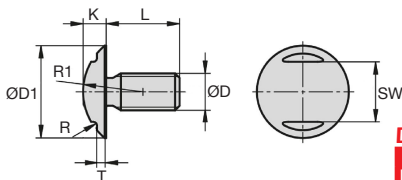

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM3-4/HDSS	M3	8	1,8	0,6	5	0,3	5,2	4	6,05 €
VTSM3-5/HDSS	M3	8	1,8	0,6	5	0,3	5,2	5	6,05 €
VTSM3-6/HDSS	M3	8	1,8	0,6	5	0,3	5,2	6	6,15 €
VTSM3-8/HDSS	M3	8	1,8	0,6	5	0,3	5,2	8	6,24 €
VTSM3-10/HDSS	M3	8	1,8	0,6	5	0,3	5,2	10	6,34 €
VTSM4-5/HDSS	M4	11	2,9	1	6	0,3	6,7	5	6,31 €
VTSM4-6/HDSS	M4	11	2,9	1	6	0,3	6,7	6	6,31 €
VTSM4-8/HDSS	M4	11	2,9	1	6	0,3	6,7	8	6,42 €
VTSM4-10/HDSS	M4	11	2,9	1	6	0,3	6,7	10	6,50 €
VTSM4-12/HDSS	M4	11	2,9	1	6	0,3	6,7	12	6,52 €

All dimensions in mm

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM5-6/HDSS	M5	14	4,0	1	8	0,4	8,6	6	6,70 €
VTSM5-8/HDSS	M5	14	4,0	1	8	0,4	8,6	8	6,88 €
VTSM5-10/HDSS	M5	14	4,0	1	8	0,4	8,6	10	6,98 €
VTSM5-12/HDSS	M5	14	4,0	1	8	0,4	8,6	12	7,14 €
VTSM5-16/HDSS	M5	14	4,0	1	8	0,4	8,6	16	7,32 €
VTSM6-8/HDSS	M6	17	5,0	1,5	10	0,6	10	8	7,21 €
VTSM6-10/HDSS	M6	17	5,0	1,5	10	0,6	10	10	7,40 €
VTSM6-12/HDSS	M6	17	5,0	1,5	10	0,6	10	12	7,58 €
VTSM6-16/HDSS	M6	17	5,0	1,5	10	0,6	10	16	7,89 €
VTSM6-20/HDSS	M6	17	5,0	1,5	10	0,6	10	20	8,07 €
VTSM8-10/HDSS	M8	20	5,0	1,5	13	0,8	13	10	7,48 €
VTSM8-12/HDSS	M8	20	5,0	1,5	13	0,8	13	12	7,69 €
VTSM8-16/HDSS	M8	20	5,0	1,5	13	0,8	13	16	8,04 €
VTSM8-20/HDSS	M8	20	5,0	1,5	13	0,8	13	20	8,32 €
VTSM8-25/HDSS	M8	20	5,0	1,5	13	0,8	13	25	8,43 €
VTSM10-12/HDSS	M10	22	6,4	1,5	15	0,9	13,5	12	9,82 €
VTSM10-16/HDSS	M10	22	6,4	1,5	15	0,9	13,5	16	10,09 €
VTSM10-20/HDSS	M10	22	6,4	1,5	15	0,9	13,5	20	10,39 €
VTSM10-25/HDSS	M10	22	6,4	1,5	15	0,9	13,5	25	10,67 €
VTSM10-30/HDSS	M10	22	6,4	1,5	15	0,9	13,5	30	10,89 €
VTSM10-37/HDSS	M10	22	6,4	1,5	15	0,9	13,5	37	11,15 €
VTSM12-16/HDSS	M12	27	7,5	1,5	19	1,0	16,3	16	11,72 €
VTSM12-20/HDSS	M12	27	7,5	1,5	19	1,0	16,3	20	12,08 €
VTSM12-25/HDSS	M12	27	7,5	1,5	19	1,0	16,3	25	12,70 €
VTSM12-30/HDSS	M12	27	7,5	1,5	19	1,0	16,3	30	13,25 €
VTSM12-35/HDSS	M12	27	7,5	1,5	19	1,0	16,3	35	13,76 €
VTSM16-20/HDSS	M16	36	9,0	1,5	24	1,1	23	20	15,44 €
VTSM16-25/HDSS	M16	36	9,0	1,5	24	1,1	23	25	16,28 €
VTSM16-30/HDSS	M16	36	9,0	1,5	24	1,1	23	30	17,12 €
VTSM16-35/HDSS	M16	36	9,0	1,5	24	1,1	23	35	18,45 €
VTSM16-40/HDSS	M16	36	9,0	1,5	24	1,1	23	40	18,94 €

All dimensions in mm

Altri prodotti...



F7-SF-SM
Visualizzatore multifunzione, Supporto - montaggio frontale



ZA
Albero per guida lineare, Acciaio temprato



PF70
Riduttore a ruota e vite senza fine, fino a 164 Nm



DOG258
Motoriduttore DC 12V e 24V DC, da 12 a 15 Nm



PSG125HC
Ingran. dritto di precisione trattato skiving, Acciaio 20NCD2 cement...



COA-COG
Staffa di montaggio per molla a gas, Staffa di montaggio piana per f...



PCS50
Pignone a catena - acciaio, 12.7mm (DIN08B-1)



PML
Piede massiccio per carichi pesanti, Ø 100, 120 o 150



LSAG
Albero scanalato a sfere, Binario - da 514 N a 15386 N



PCS8ECO
Pignone a catena - acciaio, 8mm (DIN 05B-1)



CTZYSS
Antivibrante elastico inox sgolato, Inox



LSAG
Albero scanalato a sfere, Carello - da 514 N a 15386 N

Prodotti correlati



CM
Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...



CM_CO
Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...