


# Threaded lifting ring

WBGv  RUD® Base rotates through 360°

- Lifting ring for loads liable to swivel or tilt.
- Mounted on ball bearings
- Can be rotated under load
- Easy installation, only a tapped hole required
- Heavy duty lifting ring, manufactured and tested to DIN EN1677-4
- Surface finish: Pink epoxy powder over zinc plating
- Thread is 100% electromagnetically tested for cracks, CORRUD-DT coated
- Pivots through 180°

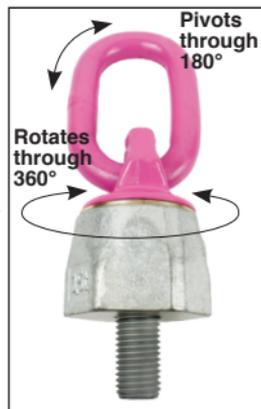


## Option


- Can be supplied with a longer thread and a mounting screw for use with a through hole or for mounting on lighter metals such as aluminium

## Info


- Conforms to EU Directive 98/37/CE

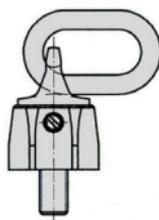


Nominal SWL  
Worst case lift  
direction

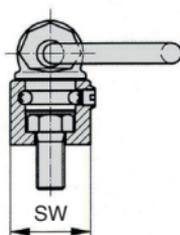

Aligned by  
hand, SWL  
increases

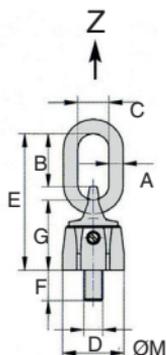

Vertical load  
SWL values doubled

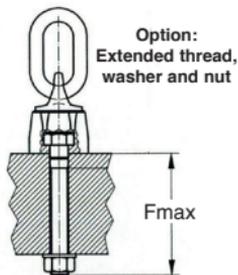

Option:  
Extended thread,  
washer and nut




## DISCOUNTS

Qty	1+	5+	10+	15+
Disc.	List -3%	-6%	On request	

Part number	Load CMU(t)			ØM	A	B	C	D	E	F	F max.	G	SW	Weight (kg)	Price each
	X	Y	Z												
WBG-V-M8	0,3	0,4	0,6	M8	8	31	29	30	76	13	102	36	27	0,18	102,28 €
WBG-V-M10	0,45	0,6	0,9	M10	8	31	29	33,5	78	17	122	38	30	0,29	108,02 €
WBG-V-M12	0,6	0,75	1,2	M12	10	49	35	42	107	21	140	47	36	0,41	114,79 €
WBG-V-M16	1,3	1,5	2,6	M16	13	46	38	48	114	25	180	56	41	0,59	123,10 €
WBG-V-M20	2	2,5	4	M20	13	54	35	62	137	33	223	67	55	1,42	206,79 €
WBG-V-M24	3,5	4,0	7	M24	18	66	40	81	173	40	255	88	70	2,63	277,98 €
WBG-V-M30	5	6,0	10	M30	22	90	50	99	221	50	330	106	85	5,09	370,98 €

\*Depending on availability - Dimensions in mm

## Our other products

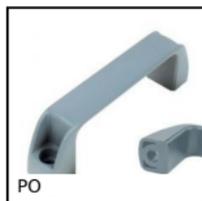

PO

Pull handle - Multi-sector, Smooth hole



BFA

Shaft locking washer, E clip



CFC

Spring loaded position switch, Electric contact



CHMR75

Worm and wheel gear reducer, up to 298 Nm



LRX

Linear roller slide, Rail - from 9410 N to 101000 N



GRP2-14-A

Spring pin ISO8740, splined ISO 8740



AC156-157

Strike for toggle latch, 25.5mm



PRF\_FIX\_STD

Fastener for aluminium profile, Standard fastener



BH02

Single housed bearing assembly, Bearing



YG2

HEAVY DUTY spur gear, Steel 35NCD6



AT10-50ECO

AT type timing pulley, Economy range -



ZDB

Machined plastic bevel gear, 2:1

## Complementary products



VRSSs

Male swivelling lifting rings stainless steel, Male swivelling - ...



VRM

Female swivelling lifting rings, Female swivelling



PPS

Lifting ring, Universal threaded



VLBG

Lifting ring, Rotating

## Altri prodotti...




PDD

Pressore a molla  
sensore di  
rilevamento, Con asta  
di comando per int...



PTRSS

Pignone tendicatenena,  
Per ambienti  
aggressivi

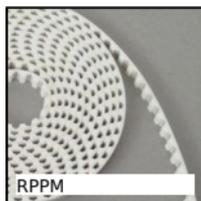

RPPM

Cinghia aperta al  
metro tipo RPP, RPP5  
Poliuretano armatura  
in acciaio



GCT

Copiglia per tubo, Clip  
per tubo



PRF\_BASE

Elementi di  
ancoraggio,  
Basamento



SEH

Attrezzo di bloccaggio  
a tirante, A tirante -  
acciaio



JFM

Cuscinetto a collare,  
Polimero universale



SVG

Chiusura a leva  
regolabile, Corsa da  
82mm a 92mm



E30

Riduttore a rinvio  
angolare, da 1.50 a 9



PCS37K

Pignone a catena  
dentatura temprata,



BTC

Tappo per tubo  
quadrato, Standard



DOMI80

Accessori di  
collegamento, Piastra

## Prodotti correlati



VRSSs

Anello di  
sollevamento,  
Orientabile maschio  
inox



VRM

Anello di  
sollevamento,  
Orientabile femmina



CRLHR

Anello di  
sollevamento,



PPS

Anello di  
sollevamento, Gancio  
universale ad avvitare