

# Symmetrical S shaped hook

New

Eco

Ste

## WSS

Wire diameters from 2 to 8mm

- Low cost range of S shaped hooks
- White galvanized steel

### Application


- Not suitable for lifting applications

### Info

- Also available in stainless steel



**NEW!**

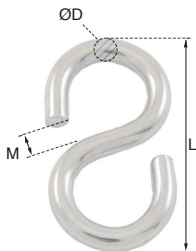

### DISCOUNTS

Qty	1+	80+	120+	160+	200+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	L	M	Weight (g)	Price each 1 to 79
WSS2-30	2,0	30	4,2	2,0	0,04 €
WSS2.5-33	2,5	33	4,0	3,0	0,08 €
WSS3-33	3,0	33	5,0	4,5	0,08 €
WSS4-40	4,0	40	5,0	9,0	0,12 €
WSS5-47	5,0	47	5,5	17,0	0,20 €
WSS6-61	6,0	61	7,0	31,0	0,32 €
WSS7-69	7,0	69	7,3	45,0	0,65 €
WSS8-75	8,0	75	10,0	58,5	0,77 €

## Altri prodotti...



BHEX

Tappo di protezione esagonale, Tecnopolimero nero



MFBC

Giunto a soffietto, Alluminio e bronzo - con ganaschia di serraggio



DTR

Pignone tendicatena, Ruota dentata in plastica



BAB

Perno autobloccante a sfere, Inox temprato




PTA50

Piede snodato con base stampata Ø50, Ø 50



DBL821

Rotella per catena, Serie 821

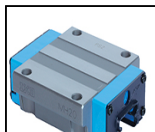

LWH

Guida lineare a sfere - Sfere acciaio, Carello - da 9320 N a 71300 N



BG

Giunto Oldham, con vite a pressione



EHD04

Riduttore coassiale, da 3.4 a 7 Nm



PSG08S

Ingranaggio dritto di precisione, Inox 303



SHSS

Vite a spalla inox 416, Inox 416 pretrattato



PGNT

Impugnatura termoplastica a T, Con perno filettato

## Prodotti correlati



WSSss

Gancio a S simmetrica, Inox



FCHN\_CHN5S

Catena dritta a maglie lunghe, Acciaio zincato