

Symmetrical S shaped hook

New

Eco

Ste

WSS

Wire diameters from 2 to 8mm

- Low cost range of S shaped hooks
- White galvanized steel

Application


- Not suitable for lifting applications

Info

- Also available in stainless steel



NEW!

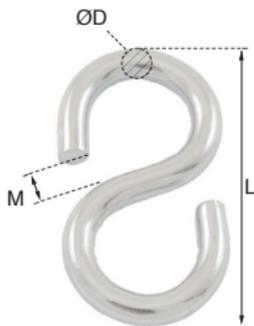

DISCOUNTS

Qty	1+	80+	120+	160+	200+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	L	M	Weight (g)	Price each 1 to 79
WSS2-30	2,0	30	4,2	2,0	0,04 €
WSS2.5-33	2,5	33	4,0	3,0	0,08 €
WSS3-33	3,0	33	5,0	4,5	0,08 €
WSS4-40	4,0	40	5,0	9,0	0,12 €
WSS5-47	5,0	47	5,5	17,0	0,20 €
WSS6-61	6,0	61	7,0	31,0	0,32 €
WSS7-69	7,0	69	7,3	45,0	0,65 €
WSS8-75	8,0	75	10,0	58,5	0,77 €

Altri prodotti...



PM3

Vite senza fine,
Acciaio non temprato



KB_WW

Manicotto chiuso a
sfere di precisione,
Economica



HG8-ECO

Ingranaggio dritto
acciaio, Acciaio C45



BMM

Manopola, zigrinata



YG1

Ingranaggio dritto
PRESTAZIONE, Acciaio
35NCD6



TUBE25_25

Tubo quadrato,
Alluminio



BDP1R

Braccio di reazione,
Serraggio standard



AT5courroie

Cinghia chiusa
posizionamento AT,
AT5 Poliuretano
armatura in acciaio



BSPT

Morsetto per guide,
Rondo



SF_ZZ

Cuscinetto radiale a
sfere, Inox



DOMI80

Slitta di regolazione
Domino 80, Slitta
DOMILINE 80



H0

Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata

...

Prodotti correlati



WSSss

Gancio a S
simmetrica, Inox



FCHN_CHNss

Catena dritta a maglie
lunghe, Acciaio
zincato