

Symmetrical S shaped hook

New

Eco

Ste

WSS

Wire diameters from 2 to 8mm

- Low cost range of S shaped hooks
- White galvanized steel

Application


- Not suitable for lifting applications

Info

- Also available in stainless steel



NEW!

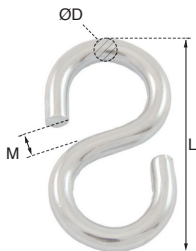

DISCOUNTS

Qty	1+	80+	120+	160+	200+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	L	M	Weight (g)	Price each 1 to 79
WSS2-30	2,0	30	4,2	2,0	0,04 €
WSS2.5-33	2,5	33	4,0	3,0	0,08 €
WSS3-33	3,0	33	5,0	4,5	0,08 €
WSS4-40	4,0	40	5,0	9,0	0,12 €
WSS5-47	5,0	47	5,5	17,0	0,20 €
WSS6-61	6,0	61	7,0	31,0	0,32 €
WSS7-69	7,0	69	7,3	45,0	0,65 €
WSS8-75	8,0	75	10,0	58,5	0,77 €

Altri prodotti...



APB_BOU

Asse per morsetti,
Tappo di sicurezza



DOMI30

Kit di raccordo, Kit di
raccordo XY



GLB

Volantino a 6 lobi,
Tecnopolimero -
Ottone



ACL-PL

Elementi di giunzione,
Piastra di fissaggio -
176x86 mm




CHMR63

Riduttore a ruota e
vite senza fine, fino a
196 Nm



BABPass

Perno autobloccante
inox temprato ad
anello, Con
impugnatura ad

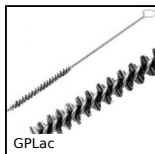

GPLac

Scovolo, acciaio



PF60

Riduttore a ruota e
vite senza fine, fino a
118 Nm



VB

Volantino a 6 lobi,
Duroplast - Ottone




MSP23

Inserto con piastrina a
incollare



RPCtc

Ruota girevole a foro
centrale, Acciaio -

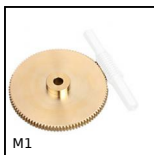

M1

Ruota per vite senza
fine, Bronzo

Prodotti correlati



WSSss

Gancio a S
simmetrica, Inox



FCHN_CHNSS

Catena dritta a maglie
lunghe, Acciaio
zincato