

Symmetrical S shaped hook

New

Eco

Ste

WSS

Wire diameters from 2 to 8mm

- Low cost range of S shaped hooks
- White galvanized steel

Application


- Not suitable for lifting applications

Info

- Also available in stainless steel



NEW!

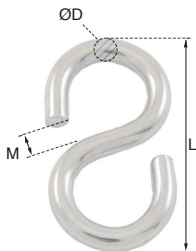

DISCOUNTS

Qty	1+	80+	120+	160+	200+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	L	M	Weight (g)	Price each 1 to 79
WSS2-30	2,0	30	4,2	2,0	0,04 €
WSS2.5-33	2,5	33	4,0	3,0	0,08 €
WSS3-33	3,0	33	5,0	4,5	0,08 €
WSS4-40	4,0	40	5,0	9,0	0,12 €
WSS5-47	5,0	47	5,5	17,0	0,20 €
WSS6-61	6,0	61	7,0	31,0	0,32 €
WSS7-69	7,0	69	7,3	45,0	0,65 €
WSS8-75	8,0	75	10,0	58,5	0,77 €

Altri prodotti...



CAP815

Catena a tapparella dritta, Stretta serie 815



BAG0

Anello di bloccaggio, Inox



MSP23

Inserto con piastrina a incollare Masterplate®, Cilindrico Ø23 con...




CHT

Motore AC asincrono trifase, 1.1 a 1.85kW



IBjss

Snodo angolare, Inox

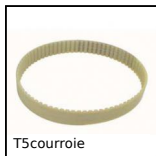


T5courroie

Cinghia di posizionamento T, T5 Poliuretano armatura in acciaio




CYS

Anello di arresto interno DIN472, interno DIN 472

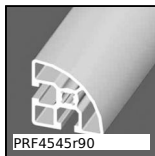

PRF4545r90

Profilato alluminio standard, 45 x 45 mm - R90°

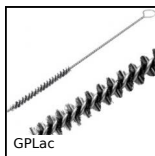

GPLac

Scovolo, acciaio



BCA

Ghiera scanalata cilindrica in acciaio,



BWU

Guida lineare di precisione, da 1510 N



GAC

Chiusura a leva con serratura, Bloccabile

Prodotti correlati



WSSss

Gancio a S simmetrica, Inox



FCHN_CHNss

Catena dritta a maglie lunghe, Acciaio zincato